

Questionnaire for glass level gauge, high-pressure version Transparent version, model LGG-TI Reflex version, model LGG-RI

Customer data

Company	Date
Name	Phone
Address	E-mail

Application data

Material standard

Material

Pressure bar (max. 250 bar)

Temperature °C (-10 ... +300 °C)

Centre-to-centre distance (M) mm (max. 4,000 mm)


Process connection

Shut-off valve

Valve arrangement

Vent

Drain

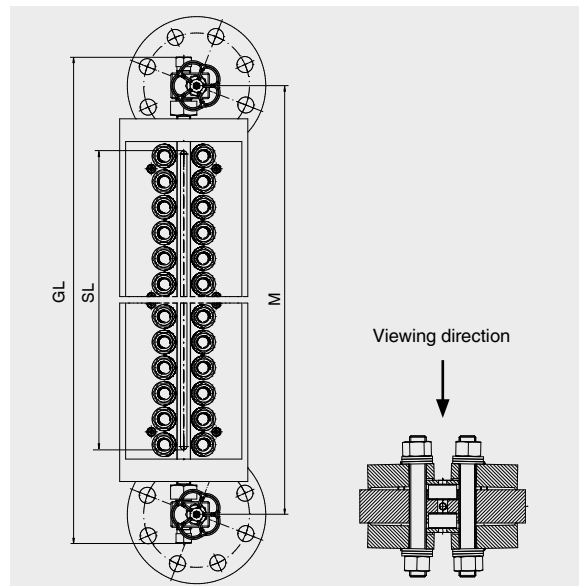

Accessories

Mica shield ¹⁾


Illumination ¹⁾

Ex requirements ²⁾

Water level mark

Scale

Scale classification

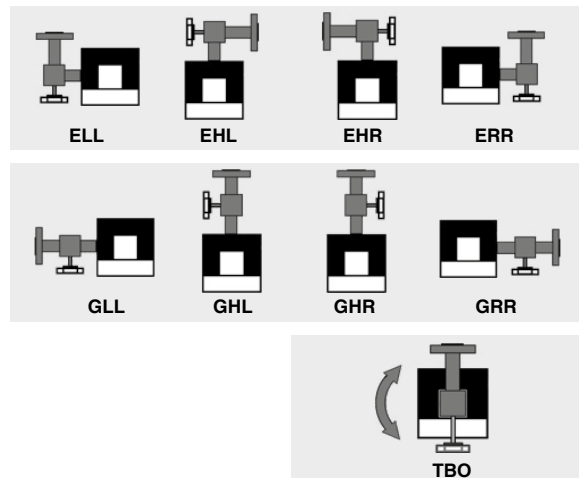

¹⁾ Only for model LGG-TI
²⁾ Only for model LGG-TI with illumination unit model LGI

Test requirements

3.1 material certificate (EN 10204)

Hydrostatic pressure test

Others _____

Additional notes



WIKA Alexander Wiegand SE & Co. KG

Alexander-Wiegand-Straße 30

63911 Klingenberg/Germany

Tel. +49 9372 132-0

Fax +49 9372 132-406

info@wika.de

www.wika.de